

Part No: 475-794F

Fabricated Fittings

Wye

Desc: 18X14 PVC RD Y SOC SCH40 100PSI G

MSRP: 4725.42

Part Code: 047

Weight(lbs): 122.511

Weight(kg): 55.57

Weight(gm): 55570

Size: 18"X18"X14"


Color: WHITE

Material: PVC

Schedule SCH 40

Connection Socket X Socket X Socket

Type Reduction

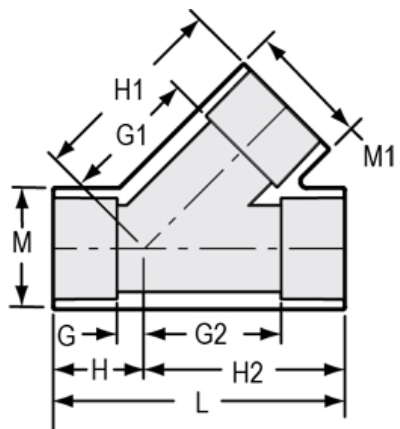

$G = 5 - \frac{3}{8}$	$G1 = 23 - \frac{13}{16}$	$G2 = 23 - \frac{3}{8}$	$H = 14 - \frac{3}{8}$	$H1 = 30 - \frac{13}{16}$
$H2 = 32 - \frac{3}{8}$	$L = 46 - \frac{3}{4}$	$M = 19 - \frac{1}{8}$	$M1 = 14 - \frac{7}{8}$	

Fabricated Dimension References:

- G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.
- H** = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.
- J** = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.
- L** = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.
- M** = Outside diameter of socket/thread hub; $\pm 1/4$ inch.
- N** = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.
- W** = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

