

Part No: 475-811F

Fabricated Fittings

Wye

Desc: 20X2 PVC RED WYE SOC SCH40 100PSI G

MSRP: 2311.11

Part Code: 047

Weight(lbs): 69.45

Weight(kg): 31.502

Weight(gm): 31502

Size: 20 X 2


Color: WHITE

Material: PVC

Schedule SCH 40

Connection Socket X Socket X Socket

Type Reduction

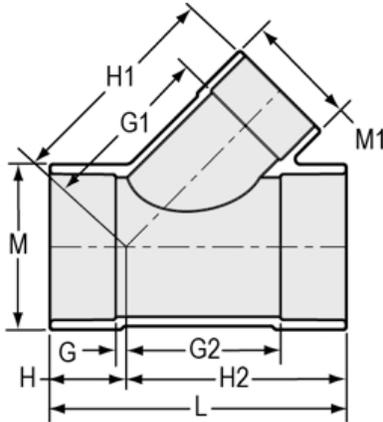

H1 = 19-3/16

H2 = 26-7/8

L = 33-3/4

M = 21-3/16

M1 = 2-11/16

G = 3-1/8

G1 = 17-7/16

G2 = 16-7/8

H = 6-7/8

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/4 & larger ± 1/2 inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; ± 1/4 inch.; wyes ± 1/2 inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/4 inch; 14" & larger ± 1/2 inch.


L = Overall length of fittings; ± 1/2 inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; ± 1/4 inch.

N = Socket bottom to socket bottom; couplings; ± 1/2 inch.

W = Height of cap; ± 1/4 inch.

Typical Fabricated Dimension References

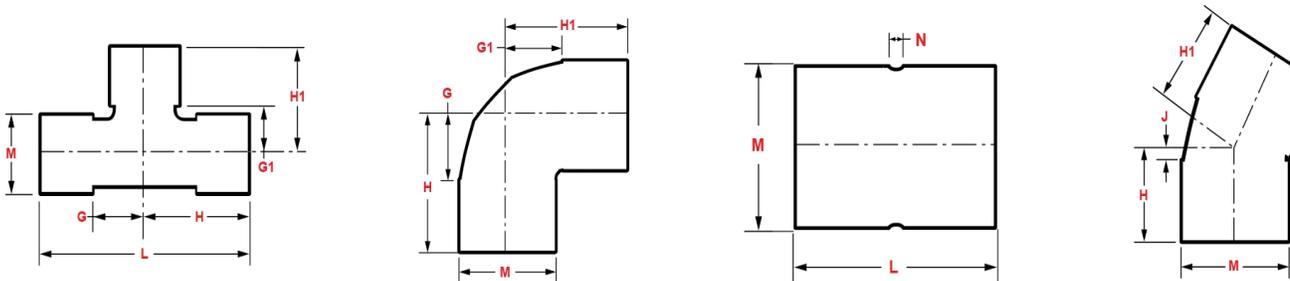

The information printed here is based on current information & product design at the time of publication and is subject to change without notification. Spears® ongoing commitment to product improvement may result in some variation. No representation, guarantees or warranties of any kind are as to its accuracy, suitability for particular application or results to be obtained therefrom. For verification of technical data or additional information, please contact Spears® Technical Service Department :: WEST COAST : (818) 364-1611 - EAST COAST : (717) 938-9006