

Part No: 475-903F

Fabricated Fittings

Wye

Desc: 24X3 PVC RED WYE SOC SCH40 100PSI G

MSRP: 2981.46

Part Code: 047

Weight(lbs): 121.651

Weight(kg): 55.18

Weight(gm): 55180

Size: 24 X 3


Color: WHITE

Material: PVC

Schedule SCH 40

Connection Socket X Socket X Socket

Type Reduction

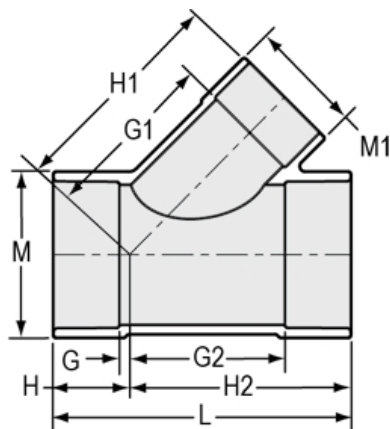

G = 3-3/8 **G1** = 21-1/4

G2 = 20-5/8

H = 8-5/8

H1 = 23-1/2

H2 = 32-5/8

L = 41-1/4

M = 25-3/8

M1 = 3-15/16

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/4 & larger ± 1/2 inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; ± 1/4 inch.; wyes ± 1/2 inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/4 inch; 14" & larger ± 1/2 inch.

L = Overall length of fittings; ± 1/2 inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; ± 1/4 inch.

N = Socket bottom to socket bottom; couplings; ± 1/2 inch.

W = Height of cap; ± 1/4 inch.

Typical Fabricated Dimension References

