

Part No: 475-912F

Fabricated Fittings

Wye

Desc: 24X12 PVC RED WYE SOC SCH40 100PSI FAB G

MSRP: 6292.26

Part Code: 047

Weight(lbs): 195.33

Weight(kg): 88.6

Weight(gm): 88600

Size: 24"X24"X12"


Color: WHITE

Material: PVC

Schedule SCH 40

Connection Socket X Socket X Socket

Type Reduction

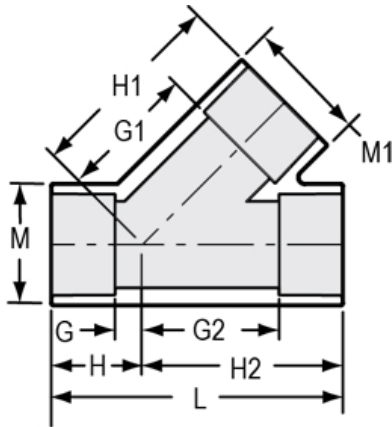

$G = 3 - 1/4$	$G1 = 27 - 5/8$	$G2 = 27 - 1/4$	$H = 15 - 1/4$	$H1 = 33 - 7/8$
$H2 = 39 - 1/4$	$L = 54 - 1/2$	$M = 25 - 3/8$	$M1 = 13 - 9/16$	

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.

L = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; $\pm 1/4$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.

W = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

