

Part No: 476-580F

Fabricated Fittings

Double Wye

Desc: 8X3 PVC RED DBL WYE SOC SCH40 100 PSI G

MSRP: 1044.02

Part Code: 047

Weight(lbs): 15.807


Weight(kg): 7.17

Weight(gm): 7170

Size: 8"X3"

Color: WHITE

Material: PVC

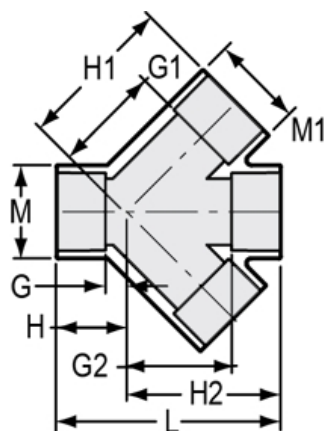

Schedule SCH 40

Connection Socket X Socket X Socket X
Socket

Type Reduction

G = 1- 5/16

G1 = 10- 7/8

G2 = 9-15/16

H = 5- 9/16

H1 = 13- 1/8

H2 = 14- 3/16

L = 19- 3/4

M = 9- 1/4

M1 = 3-15/16

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.

L = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; $\pm 1/4$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.

W = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

