

Part No: 476-622F

Fabricated Fittings

Double Wye

Desc: 10X2-1/2 PVC RED DBL Y SOC S40 100PSI G

MSRP: 1472.92

Part Code: 047

Weight(lbs): 15.152

Weight(kg): 6.873

Weight(gm): 6873

Size: 10 X 2-1/2


Color: WHITE

Material: PVC

Schedule SCH 40

Connection Socket X Socket X Socket X
Socket

Type Reduction

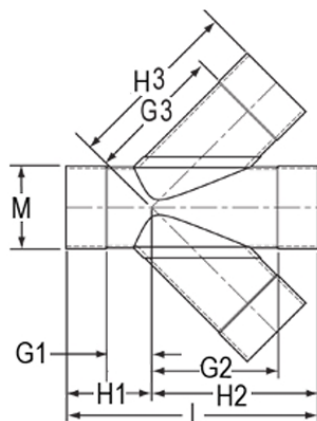

M1 = 3-1/4

G2 = 10-5/8

H = 5-1/8

H1 = 13-5/8

H2 = 15-7/8

L = 21

M = 11-1/2

G = 1/8

G1 = 11-5/8

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.

L = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; $\pm 1/4$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.

W = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

