

Part No: 476-662F

Fabricated Fittings

Double Wye

Desc: 12X2-1/2 PVC RED DBL WYE SCH40 G

MSRP: 2005.91

Part Code: 047

Weight(lbs): 21.332

Weight(kg): 9.676

Weight(gm): 9676

Size: 12 X 2-1/2


Color: WHITE

Material: PVC

Schedule SCH 40

Connection Socket X Socket X Socket X
Socket

Type Reduction

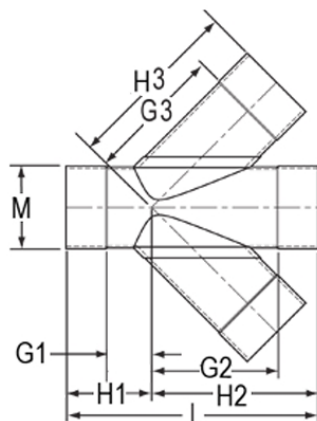

G = 1-1/8 **G1** = 13

G2 = 11-5/8

H = 5-1/8

H1 = 15

H2 = 17-7/8

L = 23

M = 13-9/16

M1 = 3-1/4

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.

L = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; $\pm 1/4$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.

W = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

