

**Part No:** 478-005

**Schedule 40 White**

**Adapter**

**Desc:** 1/2 PVC SPG FEMALE ADAPTER SPGXFPT SCH40

**MSRP:** 1.34

**Part Code:** 040

**Weight(lbs):** 0.031

**Weight(kg):** 0.014

**Weight(gm):** 14


**Size:** 1/2"

**Color:** WHITE

**Material:** PVC

**Connection** Spigot x Fipt

**Type** Standard

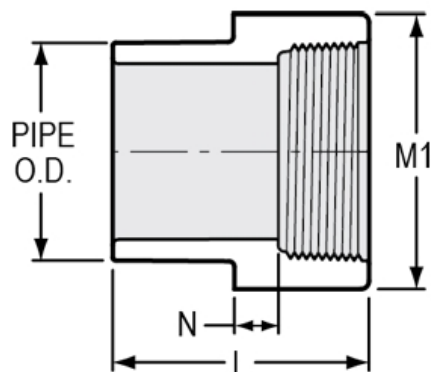

**L** = 1-19/32

**M1** = 1-3/32

**N** = 1/8

## Injection Molded Dimension References:

**G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses;  $\pm 1/32$  inch.

**H** = Intersection of center lines to face of fitting; 90° elbows tees, crosses;  $\pm 1/32$  inch.

**J** = Intersection of center lines to bottom of socket/thread; 45° elbows;  $\pm 1/32$  inch

**L** = Overall length of fittings;  $\pm 1/16$  inch.

**M** = Outside diameter of socket/thread hub;  $\pm 1/16$  inch.

**N** = Socket bottom to socket bottom; couplings;  $\pm 1/16$  inch.

**W** = Height of cap;  $\pm 1/16$  inch

## Typical Molded Dimension References

