

Part No: 478-020

Schedule 40 White

Adapter

Desc: 2 PVC SPG FEMALE ADAPTER SPGXFPT SCH40

MSRP: 6.46

Part Code: 040

Weight(lbs): 0.205

Weight(kg): 0.093

Weight(gm): 93


Size: 2"

Color: WHITE

Material: PVC

Connection Spigot x Fipt

Type Standard

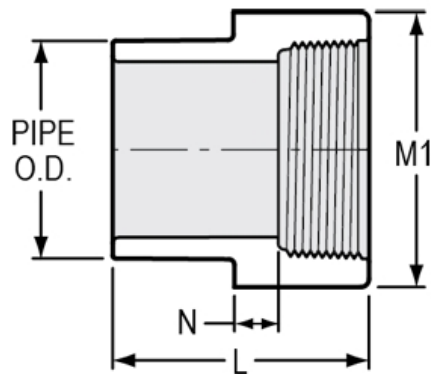

L = 2-9/16

M1 = 2-23/32

N = 7/32

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

