

Part No: 478-040

Schedule 40 White

Adapter

Desc: 4 PVC SPG FEMALE ADAPTER SPGXFPT SCH40

MSRP: 36.38

Part Code: 040

Weight(lbs): 0.829

Weight(kg): 0.376

Weight(gm): 376


Size: 4"

Color: WHITE

Material: PVC

Connection Spigot x Fipt

Type Standard

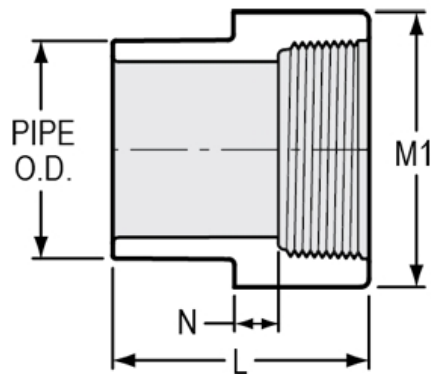

L = 4

M1 = 5-1/16

N = 9/32

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

