

Part No: 479-050F

Fabricated Fittings

Coupling

Desc: 5 PVC COUP DEEP SOC SCH40

MSRP: 143.69

Part Code: 047

Weight(lbs): 4.012

Weight(kg): 1.82

Weight(gm): 1820

Size: 5"


Color: WHITE

Material: PVC

Schedule SCH 40

Connection Deep Soc X Deep Soc

Type Standard

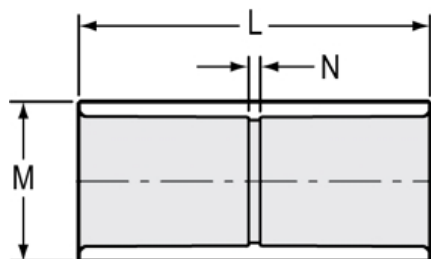

L = 15-3/4

M = 6-1/16

N = 1-3/4

Fabricated Dimension References:

- G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ inch & larger $\pm 1/2$ inch.
- H** = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.
- J** = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.
- L** = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.
- M** = Outside diameter of socket/thread hub; $\pm 1/4$ inch.
- N** = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.
- W** = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

