

Part No: 4858-007SR

Polypropylene

Union

Desc: 3/4 PP NAT UNION W/SS RING SRFPT FKM

MSRP: 91.84

Part Code: 060

Weight(lbs): 0.134


Weight(kg): 0.061

Weight(gm): 61

Size: 3/4

Color: NATURAL

Material: Polypropylene

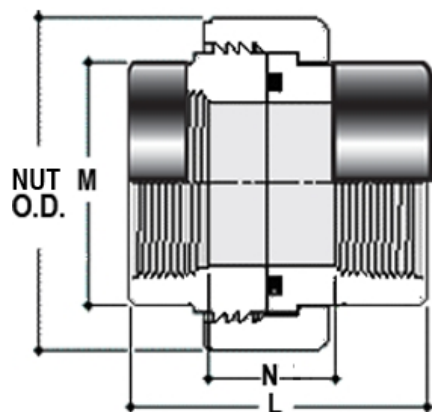

Connection SR Fipt x SR Fipt

Type Union

O-Ring FKM

Color Natural

L = 2-5/32

M = 1-3/8

N = 21/32

NUT = 2-9/32
O.D.

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

