

Part No: 5023L1-005

Valves

3-Way Ball Valve

Desc: 1/2 PVC TU2K IND 3WAY L/1 HOR FLG EPDM

MSRP: 351.71

Part Code: 615

Weight(lbs): 1.122


Weight(kg): 0.509

Weight(gm): 509

Size: 1/2"

Color: GRAY

Material: PVC

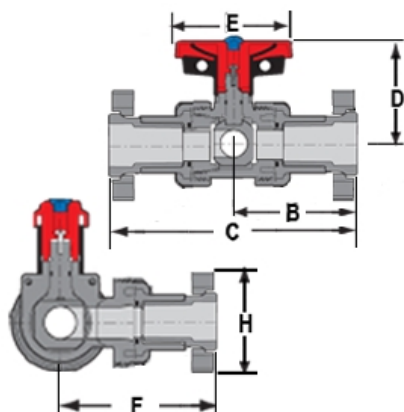

H = 3-1/2

B = 2-7/16

C = 4-3/16

D = 2-9/16

E = 2-13/16

F = 2-9/16

Type L - Port (Horizontal)

Connection Flanged

O-Ring EPDM

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

