

**Part No:** 5023L1-015C

**Valves**

**3-Way Ball Valve**

**Desc:** 1-1/2 CPVC TU2K IND 3WY L/1 HOR FLG EPDM

**MSRP:** 1572.41

**Part Code:** 617

**Weight(lbs):** 4.348


**Weight(kg):** 1.972

**Weight(gm):** 1972

**Size:** 1-1/2"

**Color:** GRAY

**Material:** CPVC

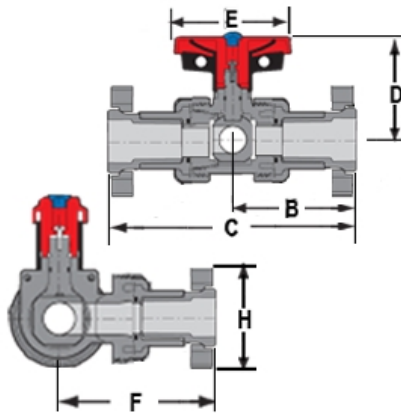

**B** = 3- 1/2

**C** = 6- 1/4

**D** = 4

**E** = 4- 3/16

**F** = 4- 3/16

**H** = 5

**Type** L - Port (Horizontal)  
**Connection** Flanged  
**O-Ring** EPDM

## Injection Molded Dimension References:

**G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses;  $\pm 1/32$  inch.

**H** = Intersection of center lines to face of fitting; 90° elbows tees, crosses;  $\pm 1/32$  inch.

**J** = Intersection of center lines to bottom of socket/thread; 45° elbows;  $\pm 1/32$  inch

**L** = Overall length of fittings;  $\pm 1/16$  inch.

**M** = Outside diameter of socket/thread hub;  $\pm 1/16$  inch.

**N** = Socket bottom to socket bottom; couplings;  $\pm 1/16$  inch.

**W** = Height of cap;  $\pm 1/16$  inch

## Typical Molded Dimension References

