

Part No: 5023L1-030C

Valves

3-Way Ball Valve

Desc: 3 CPVC TU2K IND 3WAY L/1 HOR FLG EPDM

MSRP: 3633.32

Part Code: 617

Weight(lbs): 17.037


Weight(kg): 7.728

Weight(gm): 7728

Size: 3"

Color: GRAY

Material: CPVC

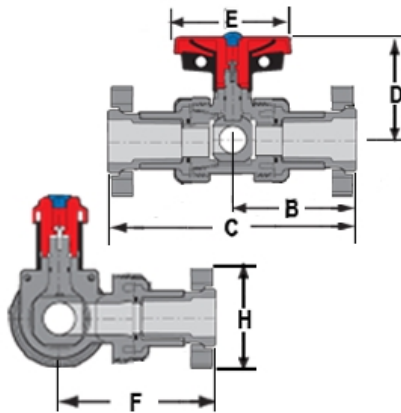

B = 6-7/8

C = 10-11/16

D = 5-7/8

E = 7-5/8

F = 6-11/16

H = 7-1/2

Type L - Port (Horizontal)

Connection Flanged

O-Ring EPDM

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

