

Part No: 5027L1-005C

Valves

3-Way Ball Valve

Desc: 1/2 CPVC TU2K IND 3WAY L/I HOR SPG EPDM

MSRP: 265.04

Part Code: 617

Weight(lbs): 0.556


Weight(kg): 0.252

Weight(gm): 252

Size: 1/2

Color: GRAY

Material: CPVC

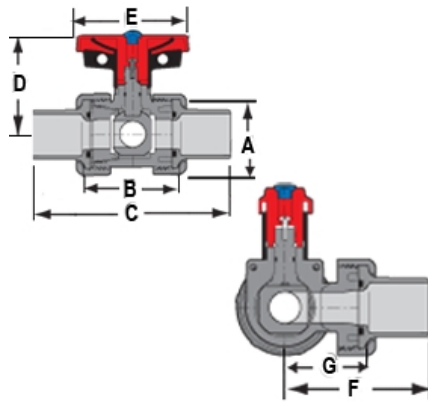

Type L - Port (Horizontal)

Connection Spigot

O-Ring EPDM

A = 1- 7/8

B = 2- 7/16

C = 4-3/4

D = 2- 9/16

E = 4-3/4

F = 2-13/16

G = 2

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

