

Part No: 5027L1-012C

Valves

3-Way Ball Valve

Desc: 1-1/4 CPVC TU2K IND 3WY L/1 HOR SPG EPDM

MSRP: 443.98

Part Code: 617

Weight(lbs): 1.795


Weight(kg): 0.814

Weight(gm): 814

Size: 1-1/4

Color: GRAY

Material: CPVC

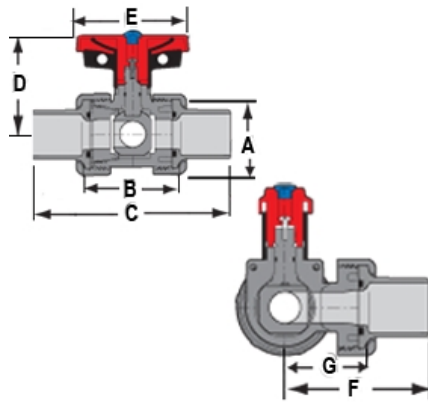

Type L - Port (Horizontal)

Connection Spigot

O-Ring EPDM

C = 6-5/16

D = 3- 5/8

E = 6-5/16

F = 4-1/16

G = 2-13/16

A = 3- 1/16

B = 3- 1/4

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

