

Part No: 5027L1-025

Valves

3-Way Ball Valve

Desc: 2-1/2 PVC TU2K IND 3WAY L/1 HOR SPG EPDM

MSRP: 1395.86

Part Code: 615

Weight(lbs): 10.604


Weight(kg): 4.81

Weight(gm): 4810

Size: 2-1/2

Color: GRAY

Material: PVC

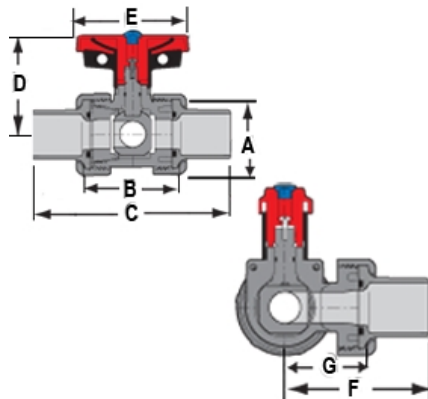

Type L - Port (Horizontal)

Connection Spigot

O-Ring EPDM

A = 5-3/8

B = 5-7/8

C = 11-3/8

D = 5-1/8

E = 11-3/8

F = 6-7/16

G = 5-5/16

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

