

Part No: 5027L1-030

Valves

3-Way Ball Valve

Desc: 3 PVC TU2K IND 3WAY L/1 HOR SPG EPDM

MSRP: 1424.36

Part Code: 615

Weight(lbs): 10.796


Weight(kg): 4.897

Weight(gm): 4897

Size: 3

Color: GRAY

Material: PVC

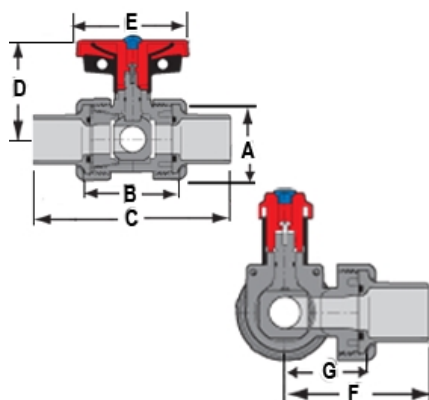

Type L - Port (Horizontal)

Connection Spigot

O-Ring EPDM

G = 5-5/16

A = 6-3/16

B = 6-7/8

C = 11-9/16

D = 5-7/8

E = 11-9/16

F = 7-3/16

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

