

Part No: 5027L1-040

Valves

3-Way Ball Valve

Desc: 4 PVC TU2K IND 3WAY L/1 HOR SPG EPDM

MSRP: 2579.62

Part Code: 615

Weight(lbs): 18.563

Weight(kg): 8.42

Weight(gm): 8420

Size: 4


Color: GRAY

Material: PVC

Type L - Port (Horizontal)

Connection Spigot

O-Ring EPDM

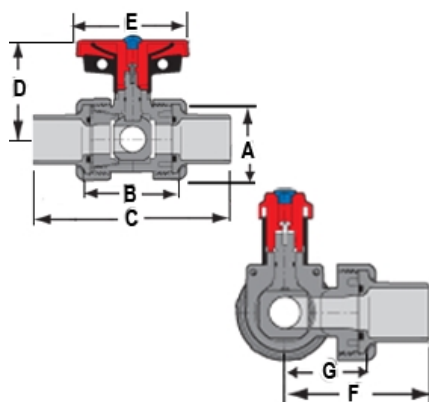

A = 7- 1/2

B = 7- 1/4

C = 12-13/16

D = 6- 3/4

E = 12-13/16

F = 8-3/4

G = 6-1/2

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

