

Part No: 5027T1-005C

Valves

3-Way Ball Valve

Desc: 1/2 CPVC TU2K IND 3WAY T/PT HOR SPG EPDM

MSRP: 265.04

Part Code: 617

Weight(lbs): 0.558

Weight(kg): 0.253

Weight(gm): 253

Size: 1/2


Color: GRAY

Material: CPVC

Type T - Port (Horizontal)

Connection Spigot

O-Ring EPDM

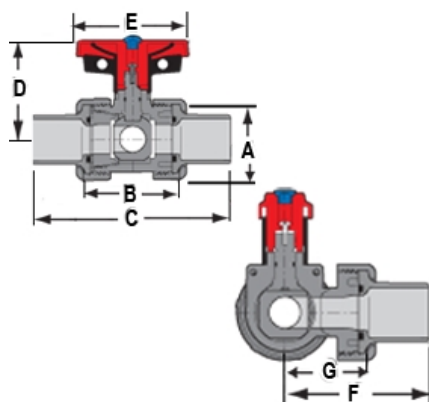

F = 2-13/16

G = 2

A = 1- 7/8

B = 2- 7/16

C = 4-3/4

D = 2- 9/16

E = 4-3/4

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

