

Part No: 5027T1-007C

Valves

3-Way Ball Valve

Desc: 3/4 CPVC TU2K IND 3WAY T/PT HOR SPG EPDM

MSRP: 315.96

Part Code: 617

Weight(lbs): 0.853


Weight(kg): 0.387

Weight(gm): 387

Size: 3/4

Color: GRAY

Material: CPVC

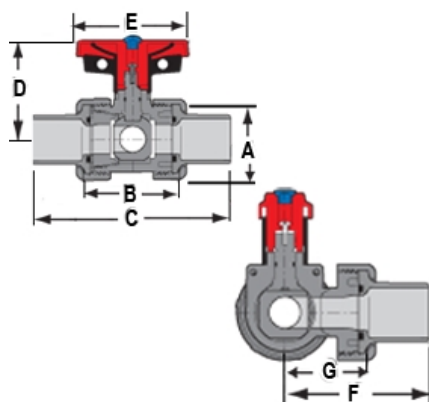

Type T - Port (Horizontal)

Connection Spigot

O-Ring EPDM

A = 2- 1/4

B = 2- 3/4

C = 5-3/8

D = 2- 7/8

E = 5-3/8

F = 3-5/16

G = 2-5/16

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

