

Part No: 5027T1-012

Valves

3-Way Ball Valve

Desc: 1-1/4 PVC TU2K IND 3WY T/PT HOR SPG EPDM

MSRP: 288.64

Part Code: 615

Weight(lbs): 1.706

Weight(kg): 0.774

Weight(gm): 774

Size: 1-1/4


Color: GRAY

Material: PVC

Type T - Port (Horizontal)

Connection Spigot

O-Ring EPDM

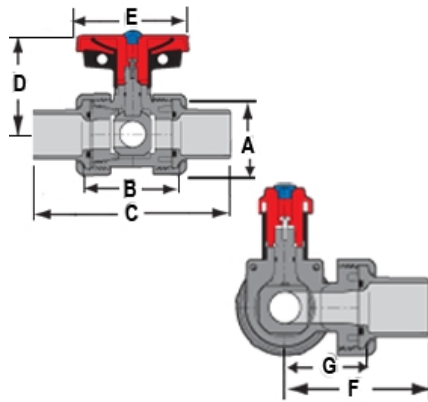

A = 3- 1/16

B = 3- 1/4

C = 6-5/16

D = 3- 5/8

E = 6-5/16

F = 4-1/16

G = 2-13/16

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

