

Part No: 5027T1-030C

Valves

3-Way Ball Valve

Desc: 3 CPVC TU2K IND 3WAY T/PT HOR SPG EPDM

MSRP: 2191.24

Part Code: 617

Weight(lbs): 10.293


Weight(kg): 4.669

Weight(gm): 4669

Size: 3

Color: GRAY

Material: CPVC

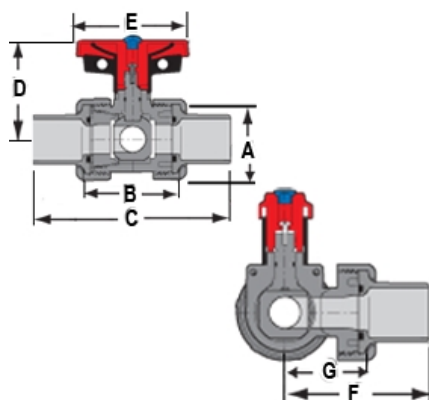

Type T - Port (Horizontal)

Connection Spigot

O-Ring EPDM

A = 6-3/16

B = 6-7/8

C = 11-9/16

D = 5-7/8

E = 11-9/16

F = 7-3/16

G = 5-5/16

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

