

Part No: 5031T1-005CSR

Valves

3-Way Ball Valve

Desc: 1/2 CPVC T/U IND 3WY HOR T/PT SR/THD FKM

MSRP: 300.23

Part Code: 617

Weight(lbs): 0.571


Weight(kg): 0.259

Weight(gm): 259

Size: 1/2"

Color: GRAY

Material: CPVC

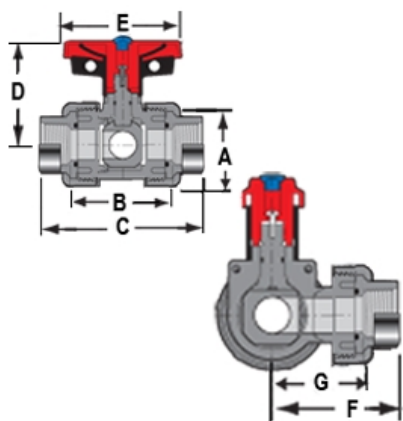

Type T - Port (Horizontal)

Connection SR Fipt

O-Ring FKM

A = 1- 7/8

B = 2- 7/16

C = 3-27/32

D = 2- 9/16

E = 2-13/16

F = 2- 9/16

G = 1-11/16

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

