

Part No: 5032L1-040C

Valves

3-Way Ball Valve

Desc: 4 CPVC T/U IND 3WAY L/1 HOR SOC FKM

MSRP: 4013.31

Part Code: 617

Weight(lbs): 19.767

Weight(kg): 8.966

Weight(gm): 8966

Size: 4"


Color: GRAY

Material: CPVC

Type L - Port (Horizontal)

Connection Socket

O-Ring FKM

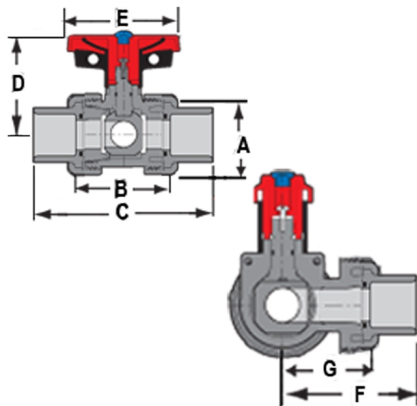

A = 7-3/4

B = 7-7/16

C = 11-15/16

D = 6-11/16

E = 9

F = 8-1/4

G = 6

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

