

Part No: 5032T1-020

Valves

3-Way Ball Valve

Desc: 2 PVC T/U IND 3WAY T/PT HOR SOC FKM

MSRP: 482.67

Part Code: 615

Weight(lbs): 3.931

Weight(kg): 1.783

Weight(gm): 1783

Size: 2"


Color: GRAY

Material: PVC

Type T - Port (Horizontal)

Connection Socket

O-Ring FKM

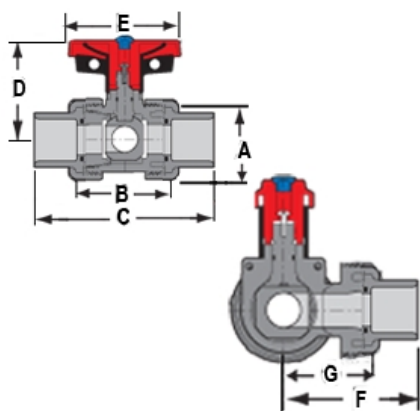

A = 4-5/16

B = 4-7/8

C = 7-7/8

D = 4-7/16

E = 5-1/16

F = 5-1/16

G = 3-9/16

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

