

Part No: 5033T1-010

Valves

3-Way Ball Valve

Desc: 1 PVC T/U IND 3WAY T/PT HOR FLG FKM

MSRP: 573.41

Part Code: 615

Weight(lbs): 2.244


Weight(kg): 1.018

Weight(gm): 1018

Size: 1"

Color: GRAY

Material: PVC

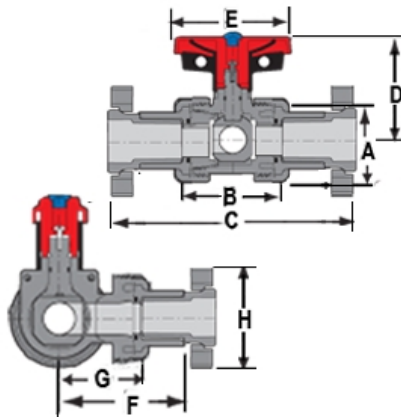

A = 2- 1/2

B = 2- 7/8

C = 5- 1/8

D = 3- 1/8

E = 3- 7/16

F = 3- 1/4

G = 2- 1/8

H = 4- 1/4

Type T - Port (Horizontal)

Connection Flanged

O-Ring FKM

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

