

Part No: 5037L1-015

Valves

3-Way Ball Valve

Desc: 1-1/2 PVC T.U IND 3WAY L/1 HOR SPG FKM

MSRP: 369.49

Part Code: 615

Weight(lbs): 2.284

Weight(kg): 1.036

Weight(gm): 1036

Size: 1-1/2


Color: GRAY

Material: PVC

Type L - Port (Horizontal)

Connection Spigot

O-Ring FKM

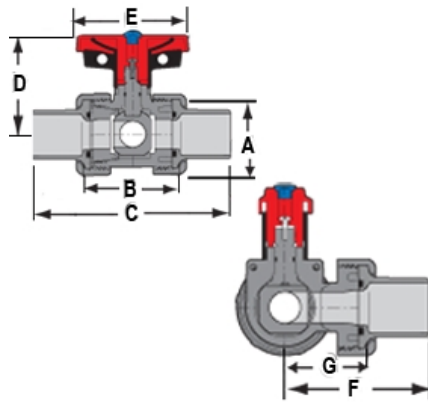

F = 4-1/2

G = 3-1/8

A = 3- 1/2

B = 3- 1/2

C = 6-3/4

D = 4

E = 6-3/4

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

