

**Part No:** 5037L1-025

**Valves**

**3-Way Ball Valve**

**Desc:** 2-1/2 PVC T/U IND 3WAY L/1 HOR SPG FKM

**MSRP:** 1484.3

**Part Code:** 615

**Weight(lbs):** 9.356

**Weight(kg):** 4.244

**Weight(gm):** 4244

**Size:** 2-1/2


**Color:** GRAY

**Material:** PVC

**Type** L - Port (Horizontal)

**Connection** Spigot

**O-Ring** FKM

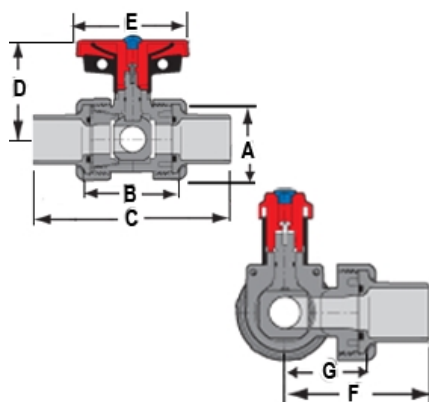

**A** = 5-3/8

**B** = 5-7/8

**C** = 11-3/8

**D** = 5-1/8

**E** = 11-3/8

**F** = 6-7/16

**G** = 5-5/16

## Injection Molded Dimension References:

**G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses;  $\pm 1/32$  inch.

**H** = Intersection of center lines to face of fitting; 90° elbows tees, crosses;  $\pm 1/32$  inch.

**J** = Intersection of center lines to bottom of socket/thread; 45° elbows;  $\pm 1/32$  inch

**L** = Overall length of fittings;  $\pm 1/16$  inch.

**M** = Outside diameter of socket/thread hub;  $\pm 1/16$  inch.

**N** = Socket bottom to socket bottom; couplings;  $\pm 1/16$  inch.

**W** = Height of cap;  $\pm 1/16$  inch

## Typical Molded Dimension References

