

Part No: 5037T1-005

Valves

3-Way Ball Valve

Desc: 1/2 PVC T/U IND 3WAY T/PT HOR SPG FKM

MSRP: 186.8

Part Code: 615

Weight(lbs): 0.534

Weight(kg): 0.242

Weight(gm): 242

Size: 1/2


Color: GRAY

Material: PVC

Type T - Port (Horizontal)

Connection Spigot

O-Ring FKM

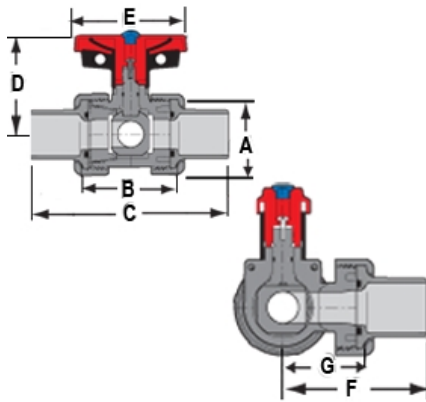

A = 1- 7/8

B = 2- 7/16

C = 4-3/4

D = 2- 9/16

E = 4-3/4

F = 2-13/16

G = 2

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

