

Part No: 5037T1-010

Valves

3-Way Ball Valve

Desc: 1 PVC T/U IND 3WAY T/PT HOR SPG FKM

MSRP: 274.36

Part Code: 615

Weight(lbs): 1.107

Weight(kg): 0.502

Weight(gm): 502

Size: 1


Color: GRAY

Material: PVC

Type T - Port (Horizontal)

Connection Spigot

O-Ring FKM

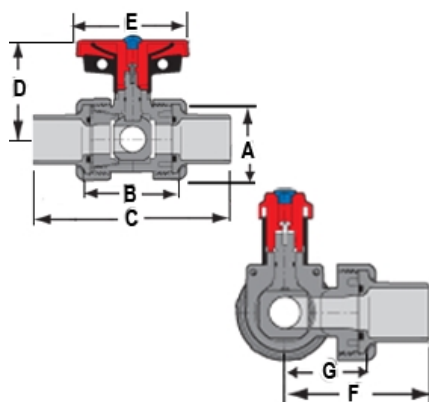

A = 2- 9/16

B = 2- 7/8

C = 5-3/4

D = 3- 1/8

E = 5-3/4

F = 3-9/16

G = 2-7/16

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

