

Part No: 5037T1-030C

Valves

3-Way Ball Valve

Desc: 3 CPVC T/U IND 3WAY T/PT HOR SPG FKM

MSRP: 2319.23

Part Code: 617

Weight(lbs): 10.346

Weight(kg): 4.693

Weight(gm): 4693

Size: 3


Color: GRAY

Material: CPVC

Type T - Port (Horizontal)

Connection Spigot

O-Ring FKM

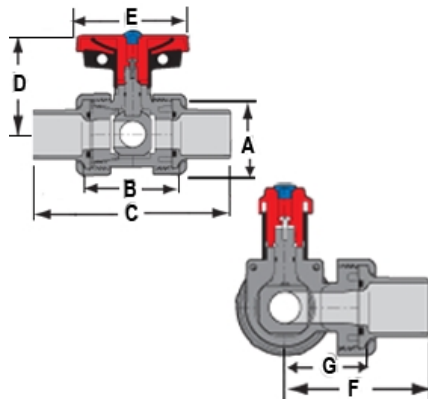

E = 11-9/16

F = 7-3/16

G = 5-5/16

A = 6-3/16

B = 6-7/8

C = 11-9/16

D = 5-7/8

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

