

Part No: 5213-007

Valves

Plug Gate Valve

Desc: 3/4 PVC PLUG GATE VALVE FLANGED BUNA

MSRP: 221.34

Part Code: 200

Weight(lbs): 0.966


Weight(kg): 0.438

Weight(gm): 438

Size: 3/4"

Color: GRAY

Material: PVC

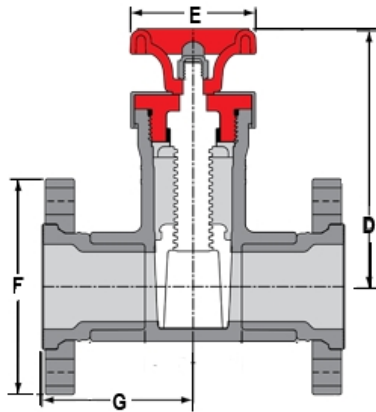

F = 3- 7/8

G = 2- 1/2

D = 4- 1/8

E = 2- 5/8

Type Plug Gate
Connection Flange x Flange
O-Ring Buna-N
Pressure Rating 150 psi @ 73° F

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

