

**Part No:** 5221-005SR

**Valves**

**Plug Gate Valve**

**Desc:** 1/2 PVC PLUG GATE VALVE EPDM SR/THD

**MSRP:** 49.21

**Part Code:** 200

**Weight(lbs):** 0.41


**Weight(kg):** 0.186

**Weight(gm):** 186

**Size:** 1/2"

**Color:** GRAY

**Material:** PVC

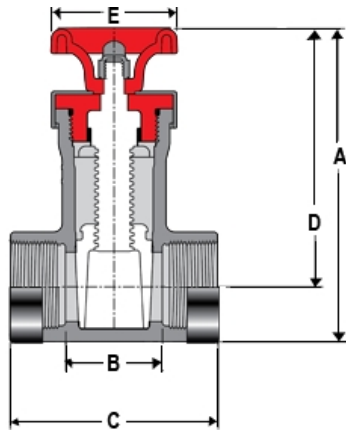

**A** = 5

**B** = 1-11/16

**C** = 3- 1/16

**D** = 4- 1/8

**E** = 2- 5/8

**Type** Plug Gate  
**Connection** SR Fipt x SR Fipt  
**O-Ring** EPDM  
**Pressure Rating** 235 psi @ 73° F

## Injection Molded Dimension References:

**G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

**H** = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

**J** = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

**L** = Overall length of fittings; ± 1/16 inch.

**M** = Outside diameter of socket/thread hub; ± 1/16 inch.

**N** = Socket bottom to socket bottom; couplings; ± 1/16 inch.

**W** = Height of cap; ± 1/16 inch

## Typical Molded Dimension References

