

Part No: 5223-012C

Valves

Plug Gate Valve

Desc: 1-1/4 CPVC PLUG GATE VALVE FLANGED EPDM

MSRP: 949.02

Part Code: 202

Weight(lbs): 2.963


Weight(kg): 1.344

Weight(gm): 1344

Size: 1-1/4"

Color: GRAY

Material: CPVC

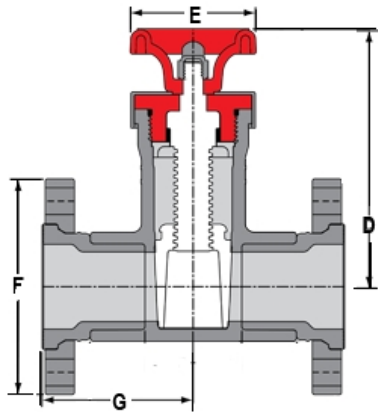

D = 7- 1/8

E = 3- 7/16

F = 4- 5/8

G = 3- 5/8

Type Plug Gate
Connection Flange x Flange
O-Ring EPDM
Pressure Rating 150 psi @ 73° F

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

