

Part No: 5223-080C

Valves

Plug Gate Valve

Desc: 8 CPVC GATE VALVE FLANGE EPD

MSRP: 5330.62

Part Code: 203

Weight(lbs): 81.057


Weight(kg): 36.767

Weight(gm): 36767

Size: 8

Color: GRAY

Material: CPVC

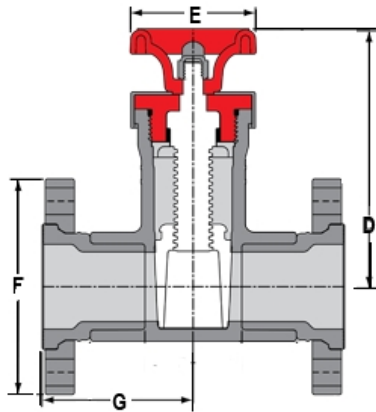

D = 20-1/16

E = 16

F = 13-1/2

G = 6-5/8

Type Plug Gate
Connection Flange x Flange
O-Ring EPDM
Pressure Rating 150 psi @ 73° F

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

