

Part No: 5233-007C

Valves

Plug Gate Valve

Desc: 3/4 CPVC PLUG GATE VALVE FLANGED FKM

MSRP: 703.93

Part Code: 202

Weight(lbs): 1.001


Weight(kg): 0.454

Weight(gm): 454

Size: 3/4"

Color: GRAY

Material: CPVC

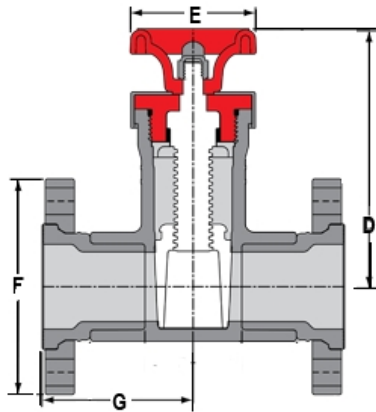

D = 4- 1/8

E = 2- 5/8

F = 3- 7/8

G = 2- 1/2

Type Plug Gate
Connection Flange x Flange
O-Ring FKM
Pressure Rating 150 psi @ 73° F

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

