

Part No: 5233-020C

Valves

Plug Gate Valve

Desc: 2 CPVC PLUG GATE VALVE FLANGED FKM

MSRP: 1319.81

Part Code: 202

Weight(lbs): 4.222

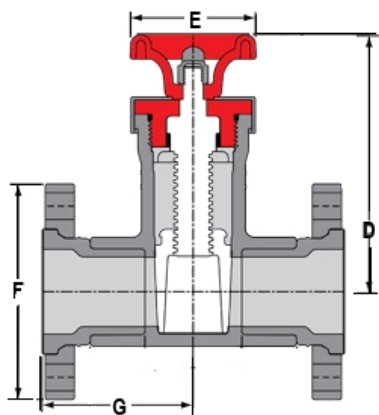
Weight(kg): 1.915

Weight(gm): 1915

Size: 2"

Color: GRAY

Material: CPVC


 $D = 7 - 1/8$
 $E = 3 - 7/16$
 $F = 5 - 15/16$
 $G = 4 - 5/32$

Type Plug Gate
Connection Flange x Flange
O-Ring FKM
Pressure Rating 150 psi @ 73° F

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

