

Part No: 542G-025C

Valves

Butterfly Check Valve

Desc: 2-1/2 CPVC BUTTRFLY CHK VLV GROOVED EPDM

MSRP: 990.59

Part Code: 290

Weight(lbs): 1.265

Weight(kg): 0.574

Weight(gm): 574


Size: 2-1/2"

Color: GRAY

Material: CPVC

Connection Grooved

O-Ring EPDM

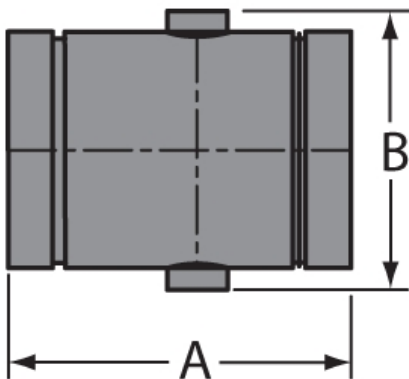

A = 5-3/4

B = 3-3/32

Cv = 123
Values

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

