

Part No: 5431A-020C

Valves

Butterfly Check Valve

Desc: 2 CPVC BUTTERFLY CHECK VALVE THD FKM

MSRP: 811.71

Part Code: 290

Weight(lbs): 0.697

Weight(kg): 0.316

Weight(gm): 316


Size: 2"

Color: GRAY

Material: CPVC

Connection Threaded

O-Ring FKM

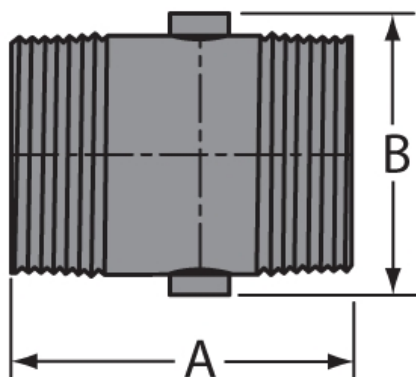

A = 5- 3/4

B = 2- 9/16

Cv = 91
Values

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

