

Part No: 5691-005BLSR

Low Extractable

Valves

Desc: 1/2 LE ANGLE PATTRN NEEDLE VALVE SR/THD

MSRP: 222.66

Part Code: 066

Weight(lbs): 0.271


Weight(kg): 0.123

Weight(gm): 123

Size: 1/2"

Color: BLUE

Material: PVC LE

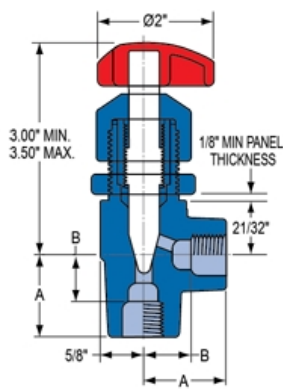

Angle Pattern

A = 3

B = 21/32

Type Angle Pattern Needle

Connection SR Fipt

Pressure Rating 235 psi @ 73° F

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

