

Part No: 5728B-060X18C

Fabricated Low Pressure

Bolted Compression Couplings

Desc: 6 CPVC ZINC BOLT RPR COUPX18 FKM SCH40

MSRP: 1942.31

Part Code: 094

Weight(lbs): 20.613


Weight(kg): 9.35

Weight(gm): 9350

Size: 6

Color: GRAY

Material: CPVC

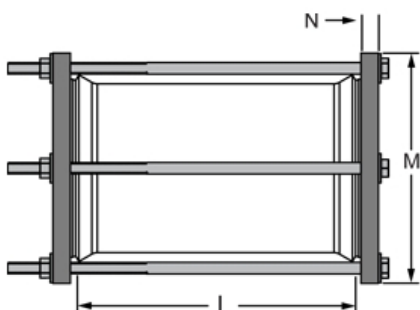

Type Compression Coupling
Connection SBR x SCH 40
Hardware ZINC
Pressure Rating 130 psi
Length 18"

L = 18

M = 10-1/8

N = 5/16

Fabricated Dimension References:

- G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ inch & larger $\pm 1/2$ inch.
- H** = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.
- J** = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.
- L** = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.
- M** = Outside diameter of socket/thread hub; $\pm 1/4$ inch.
- N** = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.
- W** = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

