

Part No: 5728B-100X18SC

Fabricated Low Pressure

Bolted Compression Couplings

Desc: 10 CPVC 316SS BOLT RPR COUPX18 FKM SCH40

MSRP: 3678.43

Part Code: 094

Weight(lbs): 32.192


Weight(kg): 14.602

Weight(gm): 14602

Size: 10

Color: GRAY

Material: CPVC

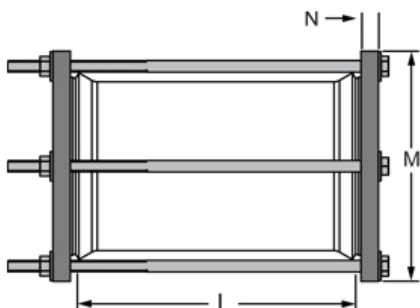

Type Compression Coupling
Connection SBR x SCH 40
Hardware SS316
Pressure Rating 130 psi
Length 18"

L = 18

M = 14-3/16

Fabricated Dimension References:

- G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ inch & larger $\pm 1/2$ inch.
- H** = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.
- J** = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.
- L** = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.
- M** = Outside diameter of socket/thread hub; $\pm 1/4$ inch.
- N** = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.
- W** = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

