

Part No: 5808-25112

Swing Joints

Riser Assemblies

Desc: 2X1-1/2 PVC SWG JNT RSR W/12 NIP TEEXMPT

MSRP: 222.79

Part Code: 030

Weight(lbs): 3.651


Weight(kg): 1.656

Weight(gm): 1656

Size: 2"X1-1/2"

Color: BLUE

Material: PVC

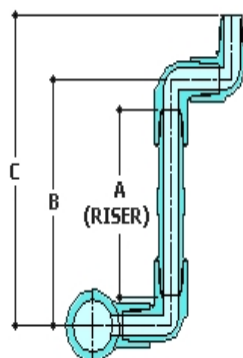

Inlet Tee
Outlet Mipt
Riser Type Buttress Thread
Type Standard
Riser Nipple Length 12

A = 12

B = 14- 1/16

C = 16-29/32

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

