

Part No: 5810-01210

Swing Joints

Riser Assemblies

Desc: 1-1/4 PVC SWING JNT RSR W/10 NIP SPGXMAT

MSRP: 121.64

Part Code: 030

Weight(lbs): 2.258


Weight(kg): 1.024

Weight(gm): 1024

Size: 1-1/4"

Color: BLUE

Material: PVC

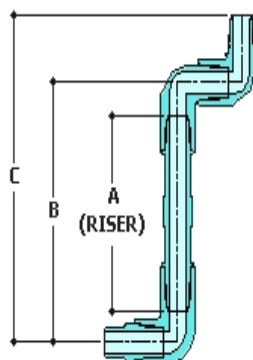

Inlet Spigot

Outlet MAT

Riser Type Buttress Thread

Type Standard

Riser Nipple Length 10

A = 10

B = 11-15/16

C = 15- 1/32

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

