

Part No: 5810-01508

Swing Joints

Riser Assemblies

Desc: 1-1/2 PVC SWING JNT RSR W/8 NIP SPGXMAT

MSRP: 140.73

Part Code: 030

Weight(lbs): 2.652


Weight(kg): 1.203

Weight(gm): 1203

Size: 1-1/2"

Color: BLUE

Material: PVC

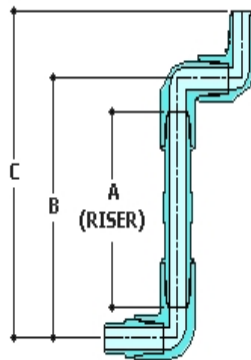

Inlet Spigot

Outlet MAT

Riser Type Buttress Thread

Type Standard

Riser Nipple Length 8

A = 8

B = 10- 7/32

C = 13- 1/2

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

