

**Part No:** 5810-01510

**Swing Joints**

**Riser Assemblies**

**Desc:** 1-1/2 PVC SWING JNT RSR W/10 NIP SPGXMAT

**MSRP:** 147.87

**Part Code:** 030

**Weight(lbs):** 2.818


**Weight(kg):** 1.278

**Weight(gm):** 1278

**Size:** 1-1/2"

**Color:** BLUE

**Material:** PVC

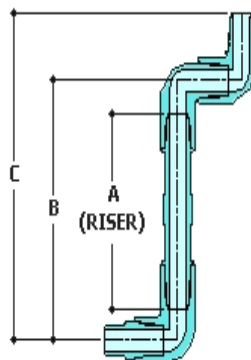

**Inlet** Spigot

**Outlet** MAT

**Riser Type** Buttress Thread

**Type** Standard

**Riser Nipple Length** 10

**A** = 10

**B** = 12- 7/16

**C** = 15- 1/4

## Injection Molded Dimension References:

**G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

**H** = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

**J** = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

**L** = Overall length of fittings; ± 1/16 inch.

**M** = Outside diameter of socket/thread hub; ± 1/16 inch.

**N** = Socket bottom to socket bottom; couplings; ± 1/16 inch.

**W** = Height of cap; ± 1/16 inch

## Typical Molded Dimension References

