

Part No: 5812-24910

Swing Joints

Riser Assemblies

Desc: 2X1 PVC SWING JNT RISER W/10 NIP TEEXMAT

MSRP: 130.84

Part Code: 030

Weight(lbs): 2.231


Weight(kg): 1.012

Weight(gm): 1012

Size: 2"X1"

Color: BLUE

Material: PVC

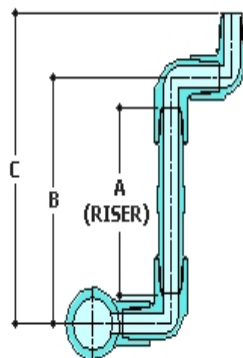

Inlet Tee
Outlet MAT
Riser Type Buttress Thread
Type Standard
Riser Nipple Length 10

A = 10

B = 11- 1/2

C = 14- 3/8

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

