

Part No: 5812-25110

Swing Joints

Riser Assemblies

Desc: 2X1-1/2 PVC SWG JNT RSR W/10 NIP TEEXMAT

MSRP: 211.32

Part Code: 030

Weight(lbs): 3.479


Weight(kg): 1.578

Weight(gm): 1578

Size: 2"X1-1/2"

Color: BLUE

Material: PVC

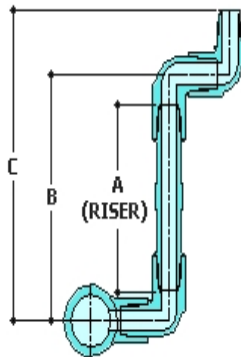

Inlet Tee
Outlet MAT
Riser Type Buttress Thread
Type Standard
Riser Nipple Length 10

A = 10

B = 12- 1/16

C = 15-11/32

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

